


MICRO VALVOLA GAS
MICRO BREATHING CELL
MIKROGASVENTILE

EVA-S

Acciaio: Inossidabile
Steel: Stainless
Stahl: Rostfrei

Specifiche: Passaggio gas: 0.03mm
Specifications: Gas passing: 0.03 mm
Spezifikationen: Größe Gas: 0.03 mm

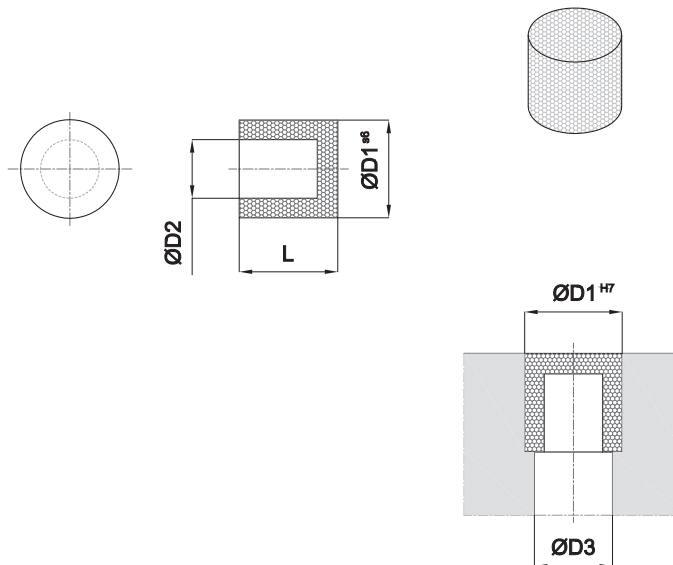

D1	L	D2	D3
3	10	2	2
4	10	2	2
5	10	2	3
6	10	3	4
8	10	4	6
10	10	6	8
12	12	6	10

Esempio di ordinativo: D1 **Order example:** D1 **Bestellbeispiel:** D1